



**DATASHEET**  
Free-Standing  
Racks  
iSEVEN  
Flex Server

**CONTEG**


## FREE-STANDING RACKS

# iSEVEN FLEX SERVER



RM7-42-80/10A-S2-H

➤ The **iSEVEN Flex Server** rack is ideal for anyone who needs to house servers properly. The iSEVEN Flex Server combines our day-to-day rack with the highly valuable features of our RSF pure server rack. Comes with a mounted frame (delivered unassembled).

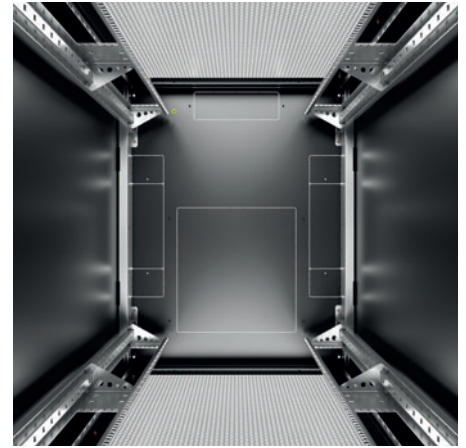

## MAIN ADVANTAGES

- Server rack for standard IT hardware up to 1000 kg
- Unmatched 86% door perforation ratio decreases server fan power consumption
- Unassembled version for transport to inaccessible spaces

COLOR:  RAL 9005  RAL 7035

## DESCRIPTION

### Sizes

- Height: 42U
- Width: 600, 800 mm
- Depth: 1000 mm

### Construction

- Robust frame design, joined by 32 M6×12 screws
- Delivered unassembled; assembly at installation site
- Quick and easy assembly
- 1.5 & 2 mm sheet steel

### Load rating

- 1000 kg

### 19" Vertical extrusions

- A-type extrusions, non-divided (600 or 800 mm wide) extrusions without horizontal holders (for

800 mm provide additional 24U of installation space); adjustable from inside, blank panels not included.

### IP rating

- Standard IP20

### Colors

- Standard RAL 7035 and 9005

### Front door

- Vented door—perforation rate 86%
- Swivel handle lock, DIN profile, universal key 333, singlepoint

### Rear door

- Vented door—perforation rate 86%
- Swivel handle lock, DIN profile, universal key 333, singlepoint

### Side panels

- Removable, with locks

### Knock-out openings—cable entry

- Universal size 300×100 mm – rear side of top and bottom plate
- Universal openings can be covered with blank panels (ordered separately)
- Extended size 500×115 mm—for 800 mm width only—both sides of top and bottom plate. Consists of 3 parts—300×115 mm and 2×—100×115 mm, each of which can be opened individually.
- Extended opening can be covered with blank panel or standard cable brush - middle opening. Opening can be protected by rubber edge



piece (DP-KP-LEM-6) or brush (DP-KP-KAR-6).

### Knock-out openings—ventilation unit installation


- Standard size 420×440 mm
- Available in top and bottom plate
- Can be covered with blank panels (ordered separately)

### Adjustable Feet

# iSEVEN Flex Server racks—technical drawings

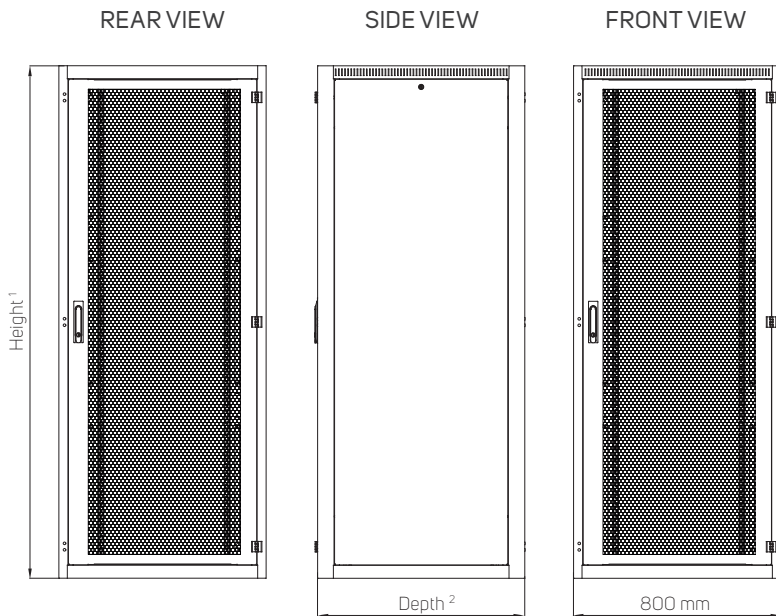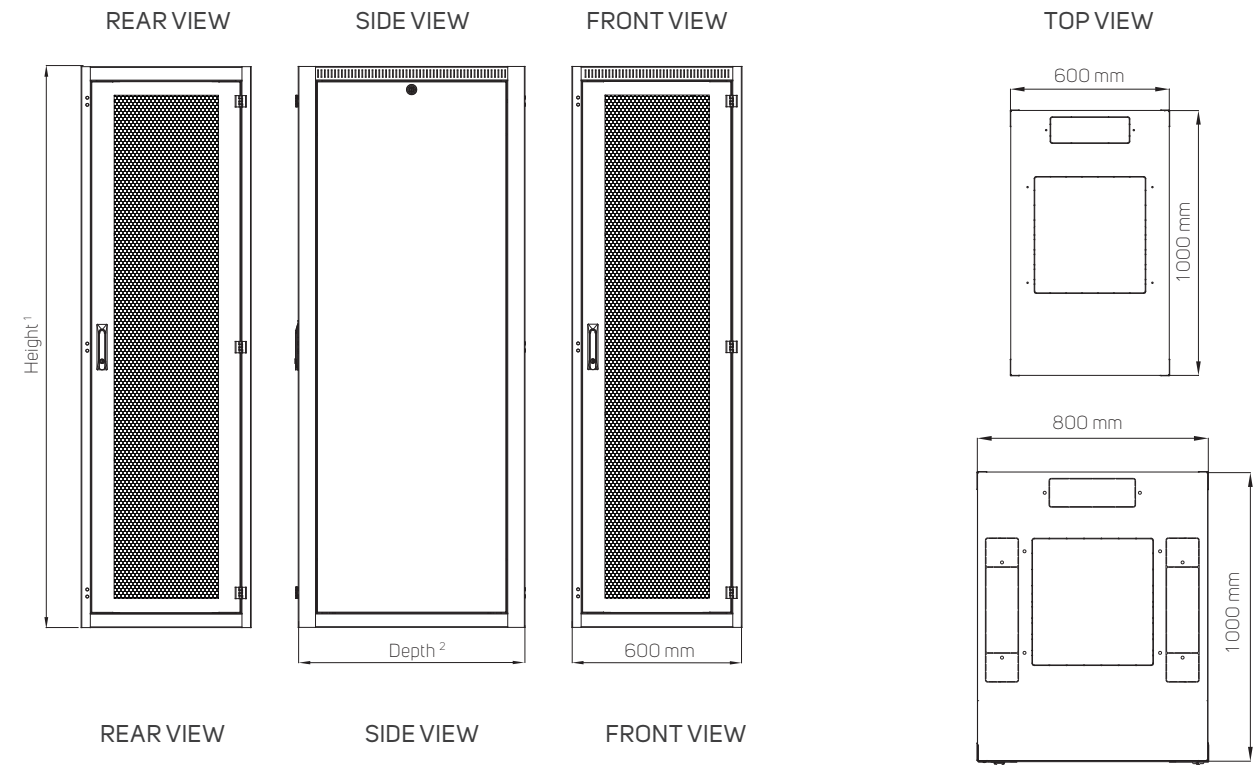

EXAMPLE—OPENED DOOR

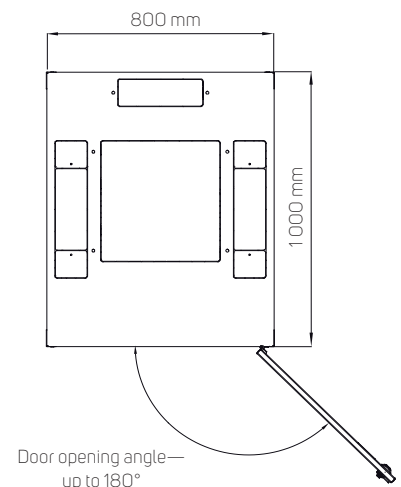

<sup>1</sup> Available heights:  
 – for width 600 mm: 42U/1978 mm  
 – for width 800 mm: 42U/1978 mm

<sup>2</sup> Available depths:  
 – for width 600 mm: 1000 mm  
 – for width 800 mm: 1000 mm

## Ventilation unit openings

420 × 440 mm

## Cable entries

300 × 100 mm 1× on top and bottom—rear

500 × 115 mm 2× on top and bottom—side (for 800 mm width)

## iSEVEN Flex Server racks—ordering and shipping information

Choose the iSEVEN Flex Server rack meeting your requirements from the table below. Each configuration comes with a separate list of components. After choosing the proper configuration and Codes, please contact your CONTEG products distributor. Please note that **all iSEVEN Flex Server racks are delivered unassembled** (in 4 separate boxes).

### iSEVEN Flex Server standard configuration

- Top and bottom covers
- 4 columns
- 2 pairs of 19" A-profile sliding vertical extrusions
- 2 pairs of A-profile vertical extrusion holders
- Front vented door—perforation rate 86 %, with swivel handle lock
- Rear vented door—perforation rate 86 %, with swivel handle lock
- 1 pair of sheet steel side panels, with locks
- 4 adjustable feet
- GND/earthing kit
- 28 mounting kits

Code	Height (in U)	Height (mm) *	Width (mm)	Depth (mm)	Useful depth (mm)	Color
RM7-42-60/10A-S1-B	42	1978	600	1000	990	RAL 7035
RM7-42-60/10A-S1-H	42	1978	600	1000	990	RAL 9005
RM7-42-80/10A-S2-B	42	1978	800	1000	990	RAL 7035
RM7-42-80/10A-S2-H	42	1978	800	1000	990	RAL 9005

\* Height in mm without feet; for feet add 16–45 mm.

Package information	For code RM7-42-60/10A-S1-B	For code RM7-42-60/10A-S1-H	Dimensions (mm) for RM7-42-60/10A-S1-B and RM7-42-60/10A-S1-H	For code RM7-42-80/10A-S2-B	For code RM7-42-80/10A-S2-H	Dimensions (mm) for RM7-42-80/10A-S2-B and RM7-42-60/10A-S1-H
Package 1	RM7-CO-42/6A-B	RM7-CO-42/6A-H	105 × 140 × 2100	RM7-CO-42/8A-B	RM7-CO-42/8A-H	105 × 140 × 2100
Package 2	RM7-TB-60/10A-S1-B	RM7-TB-60/10A-S1-H	630 × 1020 × 135	RM7-TB-80/10A-S2-B	RM7-TB-80/10A-S2-H	1005 × 1020 × 135
Package 3	RM7-DO-42/60-WVWV-B	RM7-DO-42/60-WVWV-H	550 × 70 × 1890	RM7-DO-42/80-WVWV-B	RM7-DO-42/80-WVWV-H	750 × 70 × 1890
Package 4	RM7-SP-42/100-B	RM7-SP-42/100-H	920 × 1920 × 85	RM7-SP-42/100-B	RM7-SP-42/100-H	920 × 1920 × 85

### Recommended accessories



19" vented panel with brush



Basic PDU



**CONTEG, spol. s r.o.**

Na Vitezne plani 1719/4

140 00 Prague 4

Czech Republic

Tel.: +420 565 300 358

[conteg@conteg.com](mailto:conteg@conteg.com)

[www.conteg.com](http://www.conteg.com)

**CONTEG**